




















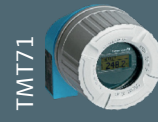












# iTEMP temperature transmitters

Communication standard	4 to 20 mA										
Field housings											
Top hat / DIN rail	 										
Head mount	 		  								
Sensor input(s)	RTD	thermocouple	1-ch universal	RTD	1-ch universal	1-ch universal	2-ch universal	2-ch universal	2-ch universal	2-ch universal	
Additional information	fixed configuration				Bluetooth	Bluetooth	SIL 2 SC 3			ethernet-apl™ advanced physical layer	
	 Zone 2		 Zone 2								
	plug-on display unit (TID10) available for head transmitters										